



**PIASTRINE DI AGGIUSTAGGIO**

PRESSURE PLATES

DRUCKPLATTEN

PST

**Acciaio:** Da cementazione 58-60 HRC (cuore 45 HRC)  
**Steel:** Case hardened 58-60 HRC (cuore 45 HRC)  
**Stahl:** Einsatzhärtung 58-60 HRC (cuore 45 HRC)

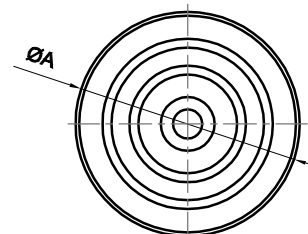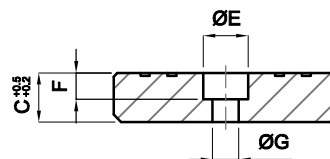

CODE	A	C	E	F	G
PST-R001	30	10,1	12	7	7
PST-R002	40	10,1	12	7	7
PST-R003	50	10,1	12	7	7
PST-R004	60	10,1	12	7	7
PST-R005	70	10,1	12	7	7
PST-R006	80	10,1	12	7	7
PST-R007	90	10,1	12	7	7
PST-R008	100	10,1	12	7	7
PST-S001	20	13,1	12	7	7
PST-S002	30	13,1	12	7	7
PST-S003	40	13,1	12	7	7
PST-S004	50	13,1	12	7	7
PST-S005	60	13,1	15	9	9
PST-S006	70	13,1	15	9	9
PST-S007	80	13,1	15	9	9
PST-S008	90	13,1	15	9	9
PST-S009	100	13,1	15	9	9
PST-T001	20	18,1	12	7	7
PST-T002	30	18,1	12	7	7
PST-T003	40	18,1	12	7	7
PST-T004	50	18,1	12	7	7
PST-T005	60	18,1	17	11	11
PST-T006	70	18,1	17	11	11
PST-T007	80	18,1	17	11	11
PST-T008	90	18,1	17	11	11
PST-T009	100	18,1	17	11	11
PST-S000	*	*	*	*	*

**Esempio di ordinativo:** Code    **Order example:** Code    **Bestellbeispiel:** Code

\* Altre dimensioni disponibili a richiesta  
 \*Other dimensions supplied on request  
 \*Andere Abmessungen auf Anfrage

**ALTRE VERSIONI DISPONIBILI A RICHIESTA**

OTHER VERSIONS AVAILABLE ON REQUEST

ANDERE AUSFÜHRUNGEN AUF ANFRAGE

